


\*Add adaptor length to the above for total length

Hoses can be cut to custom length requirements:

- Minimum length for 1/2" and 3/4" hose is 6" with 1" increments
- Minimum length for 1" and 1-1/4" hose is 9" with 1" increments

Note: All lengths are +/- 1% with adaptor

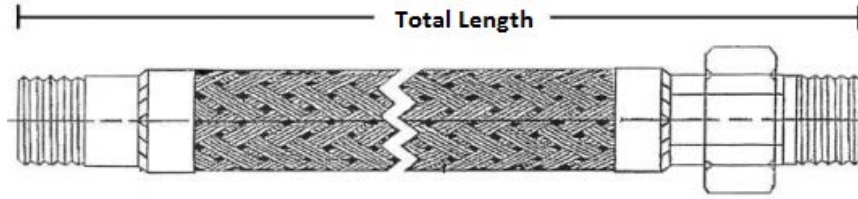

Part Number	Connection Size (Inner Diameter)	Outer Diameter	Total Length	Static Burst (PSI)	Minimum Bend Radius
V1000041	1-1/2"	1.95"	12"	1,200 (Hose Only)	10"
V1000042	2"	2.53"	12"	1,200 (Hose Only)	14"
V1000047	1-1/2"	1.95"	18"	1,200 (Hose Only)	10"
V1000048	2"	2.53"	18"	1,200 (Hose Only)	14"
V1000035	1-1/2"	1.95"	24"	1,200 (Hose Only)	10"
V1000036	2"	2.53"	24"	1,200 (Hose Only)	14"
V1000053	1-1/2"	1.95"	36"	1,200 (Hose Only)	10"
V1000054	2"	2.53"	36"	1,200 (Hose Only)	14"



Xylem Inc.  
 8200 N. Austin Avenue, Morton Grove, IL 60053  
 Phone: (847)966-3700 Fax: (847)965-8379  
[www.xylem.com/bellgossett](http://www.xylem.com/bellgossett)  
 Bell & Gossett is a trademark of Xylem Inc. or one of its subsidiaries.  
 © 2019 Xylem Inc.