


CS

60 HZ STANDARD CAPACITY 4" SUBMERSIBLE PUMPS

VFD COMPATIBLE - UP TO 80 HZ



Featuring
**QUAD-LOCK
TECHNOLOGY**

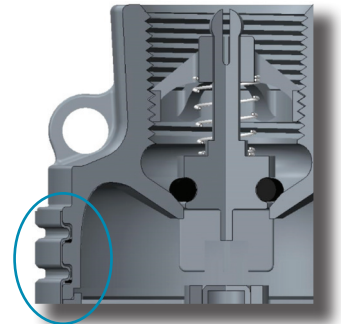

QUAD-LOCK TECHNOLOGY

4 permanently roll-formed grooves provides one of the strongest connections available
Provides the durability and sealing needed in the toughest conditions
Tensile strength tested to exceed the strength of poly and PVC pipe

FLOATING STACK DESIGN


Over 50 years of field proven design • Superior Sand Handling
AISI 304SS Bowl • Lexan® Diffuser • Noryl® Impeller

STRENGTH & DURABILITY

Stainless Steel Construction: Discharge head, motor adapter, casing bowls, cable guard and pump shaft
Engineered Polymer bearing provides excellent resistance to abrasion and wear


PEACE OF MIND

100% Performance Tested
NSF/ANSI 61 Annex G • NSF/ANSI 372

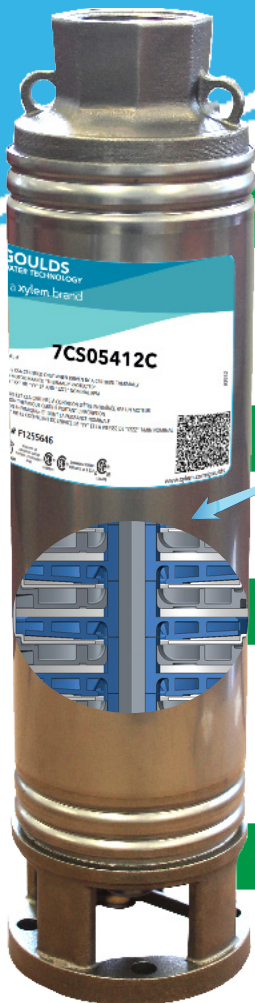

WATER END DATA

Model	Order Number	Required HP	Stages	Weight (lbs)	Length (in)
5CS	5CS05R	½	9	8	13.3
	5CS05	½	12	9	15.3
	5CS07	¾	15	11	17.4
	5CS10	1	20	13	20.8
7CS	7CS05R	½	7	6	12.1
	7CS05	½	10	7	14.2
	7CS07	¾	13	8	16.4
	7CS10	1	17	9	19.2
	7CS15	1½	22	12	24.0
10CS	10CS05R*	½	8	6	12.2
	10CS05*	½	10	7	13.6
	10CS07*	¾	14	8	16.4
	10CS10*	1	16	9	17.7
	10CS15	1½	17	12	18.8
	10CS20	2	20	13	20.8
13CS	13CS05	½	5	6	10.5
	13CS07	¾	7	7	11.9
	13CS10	1	10	8	14.0
	13CS15	1½	12	9	15.3
	13CS20	2	17	12	18.8
	13CS30	3	21	15	22.7
18CS	18CS07	¾	6	7	12.2
	18CS10	1	8	8	13.9
	18CS15	1½	11	10	16.4
	18CS20	2	14	11	19.0
	18CS30	3	19	15	23.3
25CS	25CS10	1	7	8	13.6
	25CS15	1½	9	9	15.5
	25CS20	2	11	10	17.4
	25CS30	3	15	14	21.1

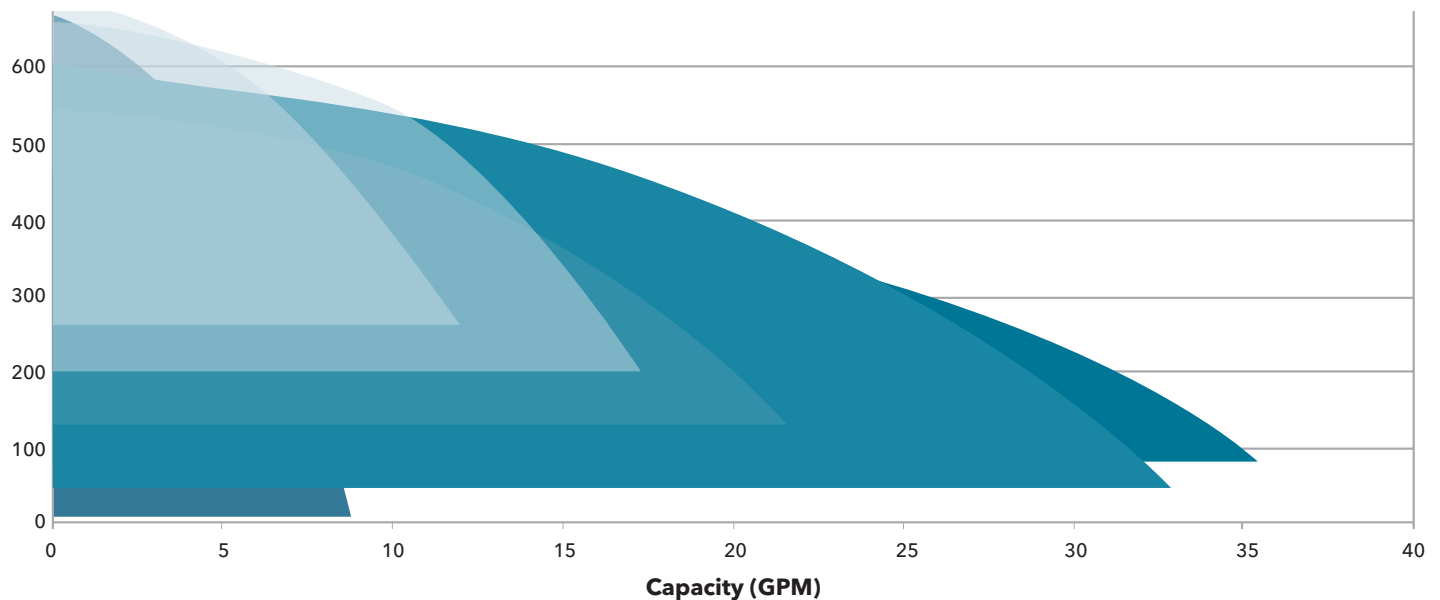

Xylem Inc.
 2881 East Bayard Street Ext., Seneca Falls, NY 13148
 Phone: (866) 325-4210 • Fax: (888) 322-5877
www.xylem.com/goulds

Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.
 Xylem and CentriPro are trademarks of Xylem Inc. or one of its subsidiaries.
 Noryl and Lexan are trademarks of GE Plastic.
 © 2022 Xylem Inc. CSSALES R4 February 2022